


Wall mount



HEX150PD series

Dimension drawing

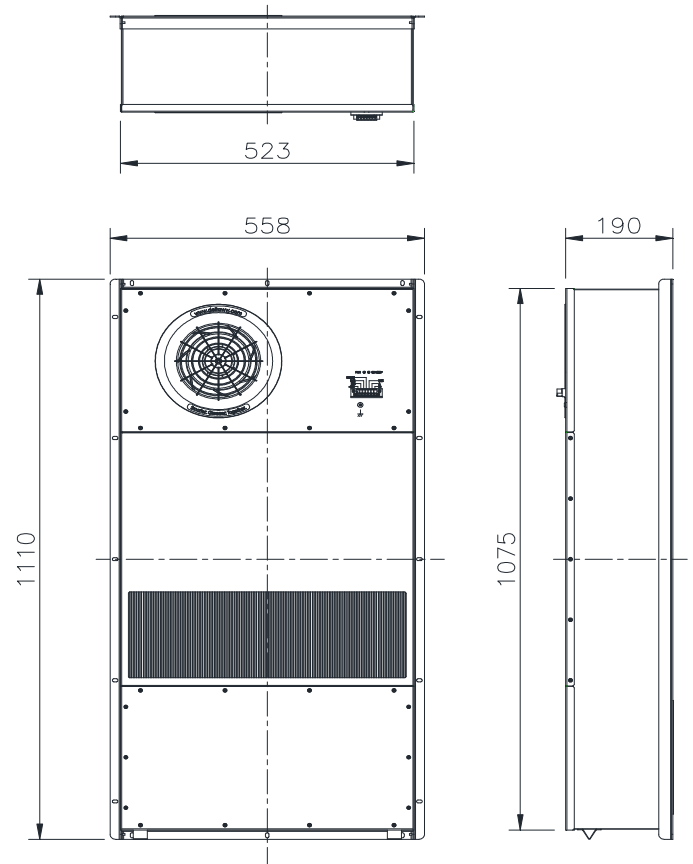

Features

- ◆ Reliable and energy efficient thermal solutions.
- ◆ IP55 waterproof at external side.
- ◆ Dry contact alarm output.

Design

- ◆ Compact size.
- ◆ Rated voltage at 48V.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

| Main feature | Unit | Specification |
|-----------------------------|--------------|--|
| Dimension (H x W x D) | mm (inch) | 1110 x 558 x 190D (43.7 x 22.0 x 7.5) |
| Cooling capacity | W/K | 150 |
| Rated voltage | VDC | 48 |
| Operating current | A | 4.8 |
| Operating Power | W | 231 |
| Operating voltage range | VDC | 40 - 60 |
| Operating temperature range | ℃ | -10 - +65 |
| Noise (1.5 meter) | dB-A | 65 |
| Weight | Kg (Lb) | 29 (64) |

* Specifications are subject to change without notice.